

Self-Laminating Safety Tag Carriers

- Cut out paper to fit and insert into the self-laminating carrier allows tags to be resistant to mild chemicals and acids
- Sturdy brass grommet provides extra durability
- Panduit PLT2S (7.40") nylon ties included for quick and easy installation
- Meet OSHA Standard 1910.147 for lockout tag 50 lb. pull force requirement



Part No.	Lamination Style	Tag Size	Pkg. Qty.
PST-4	Front only	3.50" x 5.75"	25
PST-5	Front and back		
PST-1	Front only	3.00" x 2.00"	10
PST-2		3.25" x 5.75"	5

Create Your Own Cardstock Tags


- Create your own economical cardstock tags on ink jet printers
- Economical solution for temporary, indoor tags
- Cardstock is semi-rigid tag with perforation for easy tag separation and punched hole for hanging
- Tags measure 3" x 5"
- 4 tags/sheet; 25 sheets for 100 tags per package
- Can be used with self-laminating safety tag carrier for extra durability



Part No.	Color
SEZ-TAGWH	Red and Black/White
SEZ-TAGOR	Red and Black/Orange
SEZ-TAGY	Red and Black/Yellow

Self-Laminating Cable Marker Holders for Large Cables or Cable Bundles

- Rigid vinyl, self-laminating materials
- Indoor/outdoor rated high quality rugged material resistant to abrasion
- Legend is protected by overlaminate
- Use where adhesives will not work
- Temperature range: 0°F to 176°F (-18°C to 80°C)

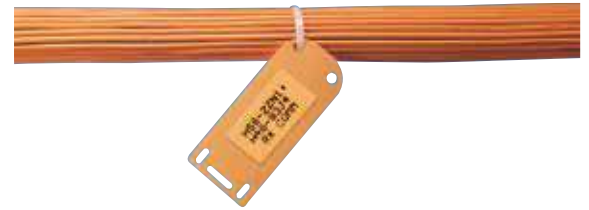


Part No.	Color	Width		Height		Tags Per Pkg.	Std. Pkg. Qty.	Std. Ctn. Qty.
		In.	mm	In.	mm			
SLCT-IG	Gray	3.00	76.2	1.31	33.3	25	1	4
SLCT-OR	Orange							
SLCT-WH	White							
SLCT-YL	Yellow							
SLCT-3	White	4.00	101.6	0.50	12.7			
SLCT-3OR	Orange							
SLCT-3YL	Yellow							

Attach with Panduit Intermediate or Standard Cross-Section Cable Ties.

Component Labels for Laser/Ink Jet Printers Supplied on 8.5" x 11" Sheets									
C200X100YJJ	White, polyester label	2.00	50.8	1.00	25.4	-	1000	5000	
Component Labels for Thermal Transfer Desktop Printers Supplied on Rolls									
C200X100YJT	White, polyester label	2.00	50.8	1.00	25.4	-	2500	10000	
Component Cassettes for Panther™ LS8 Hand-Held Thermal Transfer Printer									
C200X100YJC	White, polyester label, 200/cassette	2.00	50.8	1.00	25.4	-	1	10	

Self-Laminating Fiber Optic Cable Marker Tags

- Rigid vinyl, self-laminating material
- Indoor/outdoor rated; high quality, rugged material resistant to abrasion; legend is protected by overlaminate; use where adhesives will not work
- Temperature range: 0°F to 176°F (-18°C to 80°C)

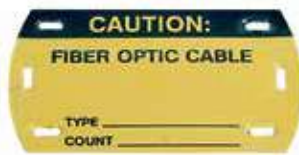

Part No.	Legend	Color (Legend/Background)	Width		Height		Tags Per Pkg.	Std. Pkg. Qty.	Std. Ctn. Qty.
			In.	mm	In.	mm			
PST-FO	CAUTION FIBER OPTIC CABLE TYPE _____ COUNT _____	Black/ Yellow	3.50	89.0	2.00	51.0	5	1	40
PST-FOBLNK	BLANK	Yellow							

Order number of packages required in multiples of Std. Pkg. Qty.

Ground Warning Tags

- Rigid polyethylene material
- Indoor/outdoor rated; high quality, rugged material resistant to abrasion; use where adhesives will not work
- Temperature range: -30°F to 250°F (-34°C to 121°C)



Part No.	Legend	Color (Legend/Background)	Width		Height		Tags Per Pkg.	Std. Pkg. Qty.	Std. Ctn. Qty.
			In.	mm	In.	mm			
PT-BGND	NETWORK BUILDING GROUND	Green/ Yellow	2.75	70.0	1.38	35.0	100	1	5
PT-GND	WARNING GROUND WIRE DO NOT REMOVE	Black/ Yellow							
PT-TGND	WARNING TELEPHONE CO. REPAIR SERVICE								

Order number of packages required in multiples of Std. Pkg. Qty.