

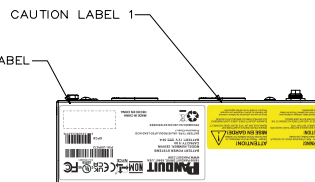
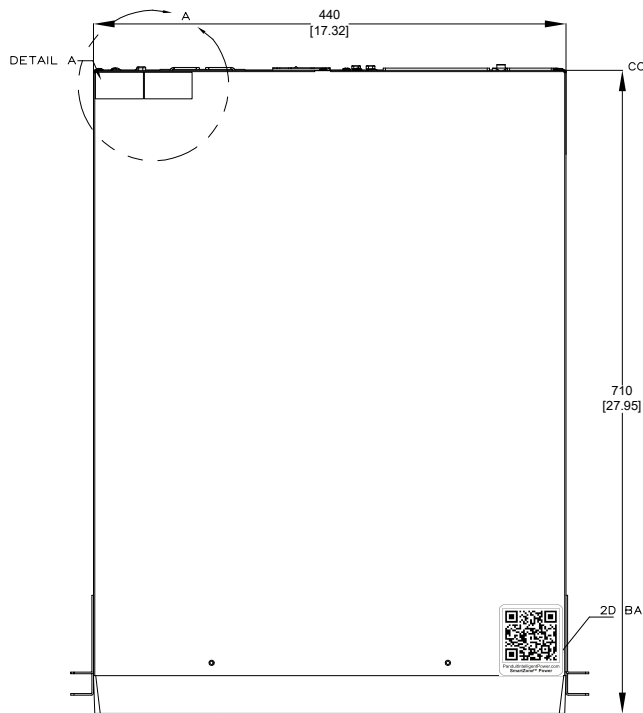


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

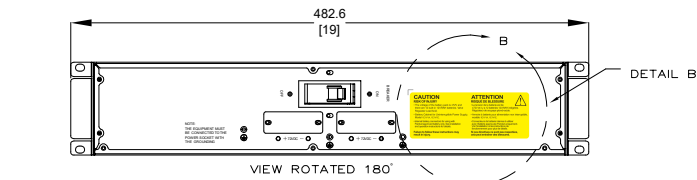

DETAIL A  
SCALE 1:2

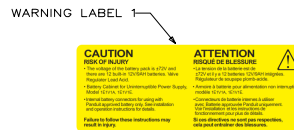

DETAIL B  
SCALE 1:2

**SPECIFICATION:**

**1. STANDARD:**

USE WITH UPS CAPACITY: 3 KVA  
 BATTERY TYPE: VALVE REGULATED LEAD ACID—NON SPILLABLE  
 NOMINAL INPUT/OUTPUT VOLTAGE: 72VDC  
 BREAKER TYPE: 63A/1P  
 WEIGHT OF Pb(LEAD): 20.4KG  
 WEIGHT OF H2SO4(SULFURIC ACID): 2.4KG

**2. ADDITIONAL:**

NONE

**3. ACCESSORY COMPONENTS:**


STABILIZER BRACKET, QTY:(4)  
 INSTALLATION EARS, QTY:(2)  
 SAFTY WARNING SHEET,QTY:(1)  
 INCLUDES P/N:URMKIT2 INSTALLATION RAIL KIT, QTY:(1)  
 REFER TO ASSOCIATED DRAWINGS FOR PHISICAL DIMENSIONS AND SPECIFICATIONS  
 EBP POWER CABLE, QTY:(1)  
 INCLUDES P/N:UVDO72 BATTERY CARTRIDGE SET,QTY:(1)

**NOTES:**

1. PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSIONS ARE IN INCHES
2. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES
3. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
4. ALL PURCHASED ITEMS CONFORM TO C2-0834 PANDUIT SPECIFICATION FOR CHEMICAL SUBSTANCES TO BE CONTROLLED IN PRODUCT AND PACKAGING

**IDENTIFICATION:**

PART NUMBER	DESCRIPTION	SHIPPING WEIGHT (KG)
UVP072	VRLA EXTERNAL BATTERY PACK (EBP) 2*6PCS 72V (9AH BATTERIES) CHASSIS, BATTERIES, AND RAIL KIT INCLUDED, FOR 3KVA UPS ONLY	55.60

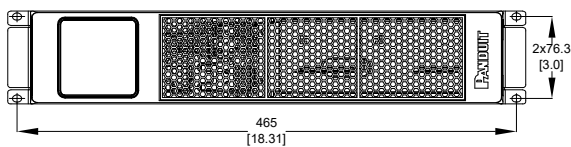

REV	DATE	BY	CHK	DESCRIPTION	ECN	
01A	08/17/2022	DL	ZKZ	QJM/DUB		
00A	08/17/2022	DL	ZKZ	QJM/DUB		
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN

EXTERNAL BATTERY PACK  
UVP072

CUSTOMER DRAWING

UVP072/01

UVP072-DC/01A

UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE IN (mm)

DATE: 08/17/2022

DESIGN: N/A

UVP072-DC

REV: D

SHT 1 OF 2

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.



18900 PANDUIT DRIVE, 60487, USA  
WWW.PANDUIT.COM

BATTERY POWER SYSTEMS  
MODEL NUMBER: 2E0V0N  
CAPACITY: 9 Ah  
BATTERY: 2 V 50 A




BATTERY TYPE: VALVE REGULATED LEAD ACID  
Protective Class 1

PROHIBIDO SU USO EN EXTERIORES



MADE IN CHINA  
HECHO EN CHINA

EXTERNAL BATTERY PACK:  
UVP072

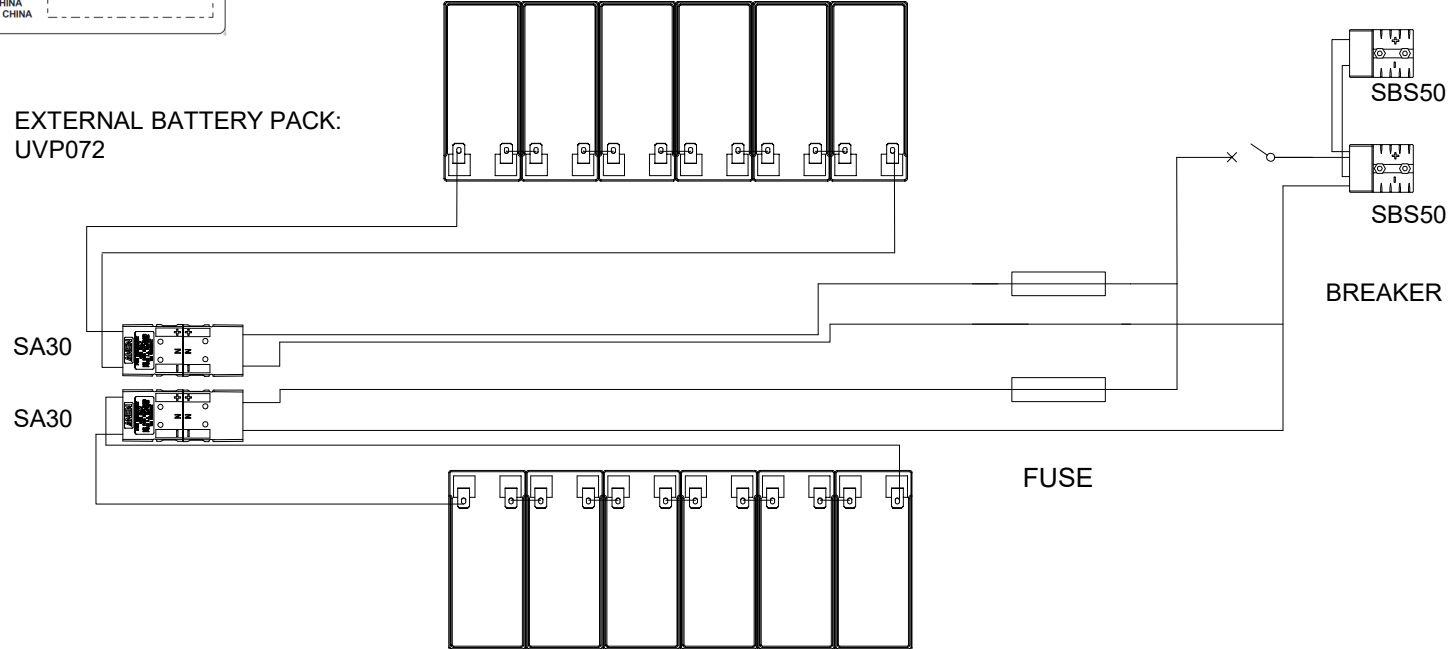

LEGEND			
	DESCRIPTION		DESCRIPTION
	DESCRIPTION		DESCRIPTION
	DESCRIPTION		DESCRIPTION
	DESCRIPTION		DESCRIPTION
	DESCRIPTION		DESCRIPTION

EXTERNAL BATTERY PACK UVP072									
CUSTOMER DRAWING									
NO REVISION CODE									
UVP072-01									
UVP072-DC/01A									
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: MM (IN)									
N/A									
PANDUIT									
PART NUMBER: UVP072-DC									
DATE: 08/17/2021									
DRAWN BY: MJD									
CHECKED BY: MJD									
APPROVED BY: MJD									
ECN: VARIOUS									
SHEET NUMBER: SH1 OF 2									

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
001	08/17/2021	ZRZ	GM/DAB		A-ADDED NOTE BELOW VIEW B-KIT WAS UPGRADED C-UPDATED DESCRIPTION D-NOTCH REMOVED IN METAL	UVP072
002	08/17/2021	ZRZ	GM/DAB		RELEASE TO PRODUCTION	UVP072
003	08/17/2021	ZRZ	GM/DAB		RELEASE TO PRODUCTION	UVP072