

Fiber Ladder Rack Mount Enclosure

specifications

The Fiber Ladder Rack Mount Enclosure shall offer great versatility regarding installation options. It shall be designed to work in an overhead or underfloor environment, other options include wall mount consolidation box. The enclosure shall accept any Panduit Opticom cassette or FAP and shall feature a removable panel that allows for easy cable access. The FLRME shall be mounted on any wire baskets, ladder trays, wire grids, and wall mounts.



FLRME

technical information

Part Number	Height in (mm)	Width in (mm)	Depth in (mm)
FLRME	1.7 (43)	10.7 (271)	8 (203)
Mounting option	Vertical or horizontal wall mounting or low profile raised floor system (minimum depth of 1.7")		
Packaging	FLRME Box includes molded rings 1.5X3 Box includes raw slack spool Box includes grommet edging, solid 100', adhesive poly Box includes loop tie, cable tie		


key features and benefits

Modularity	Accepts all Opticom Modules; individual modules snap in and out
Metal supports	Mounting brackets pinch on to the fiber ladder rail and can be oriented up or down
Cable Management	Spools can be added for fiber slack management
Center metal supports	Supports raised floor panels
UL approved	Suitable for use in air handling spaces



applications

The Fiber Ladder Rack Mount Enclosures offers great versatility regarding installation options and is designed to work with overhead and underfloor systems as a consolidation point. Recommended applications include wire baskets, ladder trays, wire grids, and wall mounts. Fiber Ladder Rack Mount Enclosures save time and money by reducing the amount of time required to complete moves, adds and changes. Troubleshooting is also simplified as the connections can be tested and certified before installation.

Fiber Ladder Rack Mount Enclosure

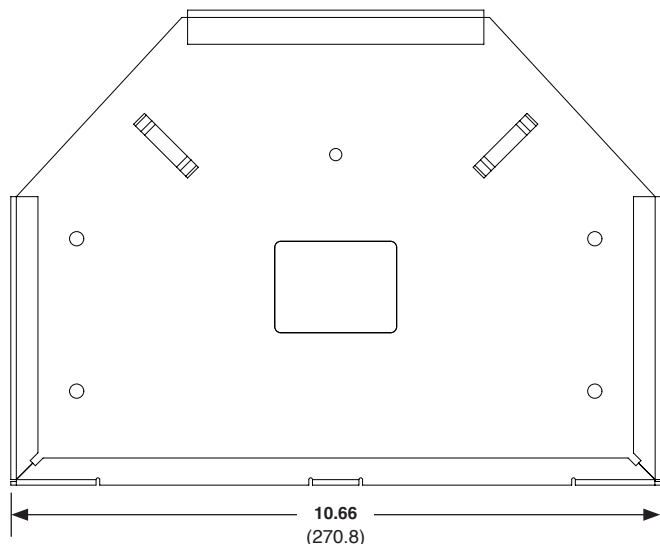

Cover removed for clarity in this view

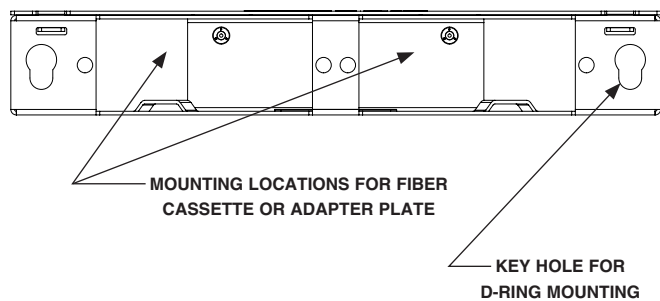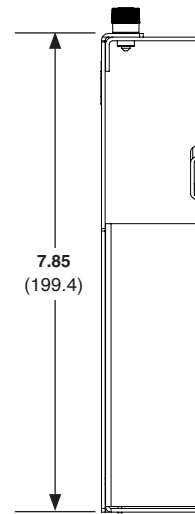

Dimensions are in inches. (Dimensions in brackets are metric).

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT CANADA
Markham, Ontario
cs-cdn@panduit.com
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
cs-emea@panduit.com
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
cs-ap@panduit.com
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
cs-japan@panduit.com
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
cs-la@panduit.com
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
cs-aus@panduit.com
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com

Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

PANDUIT[®]

©2018 Panduit Corp.
ALL RIGHTS RESERVED.
Printed in the U.S.A.
RKSP147--WW-ENG
Replaces WW--RKSP55
8/2018