


NetKey® White Flush Mount Patch Panels

specifications

Flush mount patch panels shall consist of a white, metal panel with molded white, rear snap-in faceplates. Patch panels shall accept all NetKey® Modules for UTP, fiber, or A/V applications and shall mount to standard 19" racks. Patch panels shall be available in 24-port and 48-port standard density, as well as 48-port high density for 48-port count in 1 RU. Flush mount patch panels shall be easy to identify with pre-numbered ports. Angled patch panels shall be designed at an optimum angle to help route the cable.

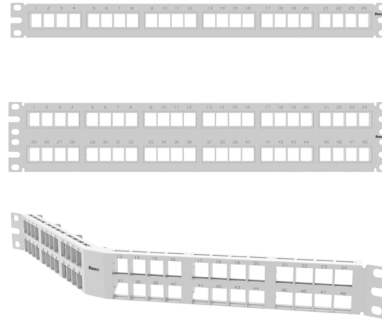

technical information

Mounting options:	Mounts to standard EIA 19" racks or 23" racks with optional extender brackets
Material:	Stamping is white CRS and faceplate is white ABS
Packaging:	Packaged with appropriate pre-installed snap-in faceplates and a set of mounting screws (#12-24)

key features and benefits

Modular	Accepts all Panduit® NetKey® Modules to mix and match media types in the same panel
Angled design	Allows cable to flow to each side of the rack and minimizes the need for horizontal cable managers by enabling patch cords to be routed directly into vertical cable managers which leads to increased closet density
Optional strain relief bars	Help support and manage cables
Optional filler panels	Fill unused rack openings to provide a clean and consistent look

applications

NetKey® Flush Mount Patch Panels in white are ideal for multi-media applications. They accept all NetKey® Modules and mount flush with the front of the rack for a clean appearance. Various styles and port densities are available to fit most needs. Angled patch

panels are available for applications in which rack space is limited. The design allows cable to flow to each side of the rack, minimizing the need for horizontal cable managers and increasing the density of the rack space.

White Flush Mount Panels, Flat

24-port, 1 RU:	NKPP24FMWH
48-port, 2 RU:	NKPP48FMWH

White Flush Mount Panels, Angled

24-port, 1 RU:	NKPPA24FMWH
48-port, 2 RU:	NKPPA48FMWH

Flush Mount Panels, High Density

48-port, 1 RU:	NKPP48HDWH
48-port, 1 RU, Angled:	NKPPA48HDWH










Strain Relief Bars

Straight:	SRBS19BL-XY
Extended, 2":	SRB19BLY
With hook and loop cable ties:	SRBM19BLY
With adjustable clips:	SRBWCY
Deep, 5":	SRB19D5BLY
Deep, 7":	SRB19D7BLY
Multi-depth:	SRB19MDBL

Extender Brackets

1 RU:	PEB1
2 RU:	PEB2

NetKey® White Flush Mount Patch Panels

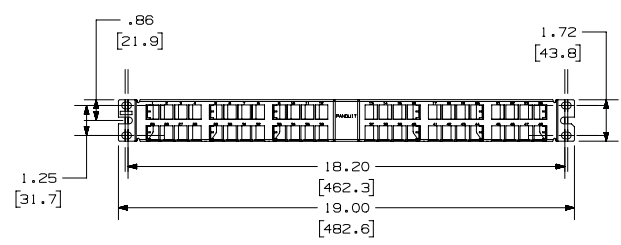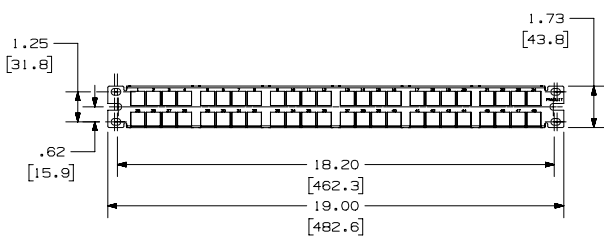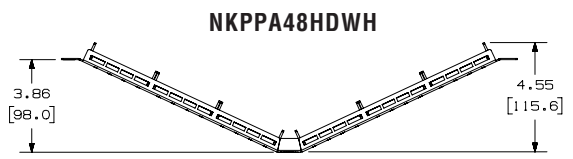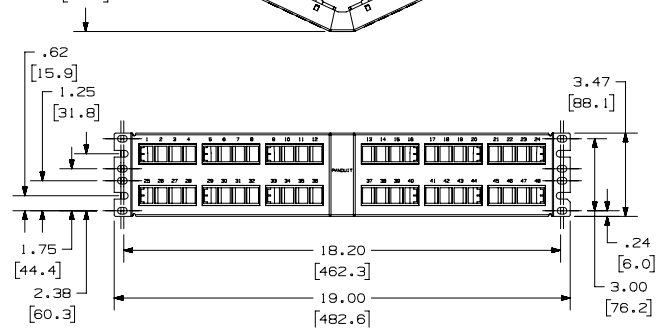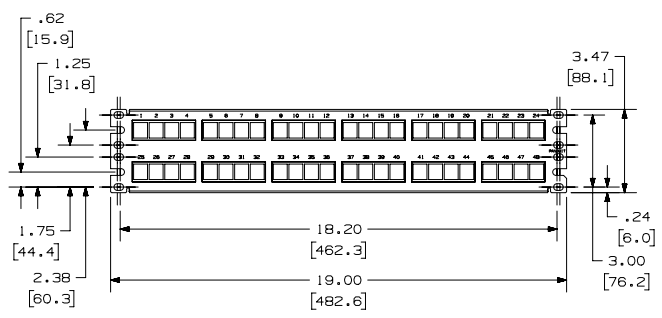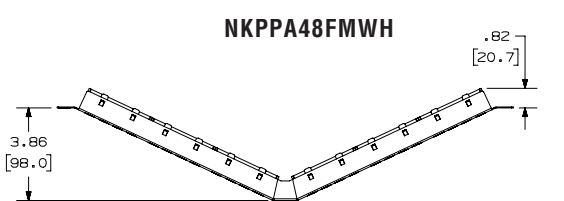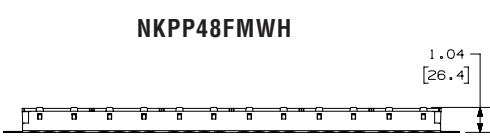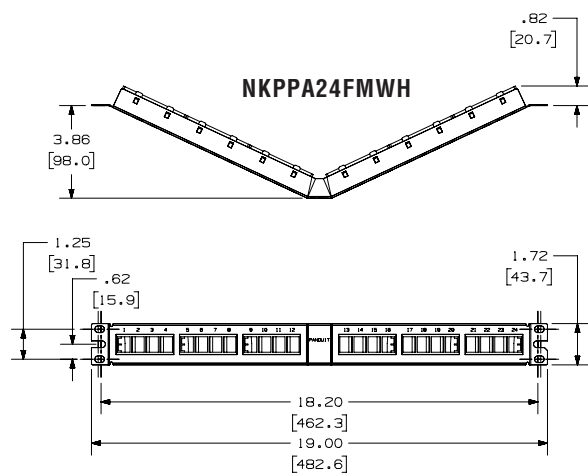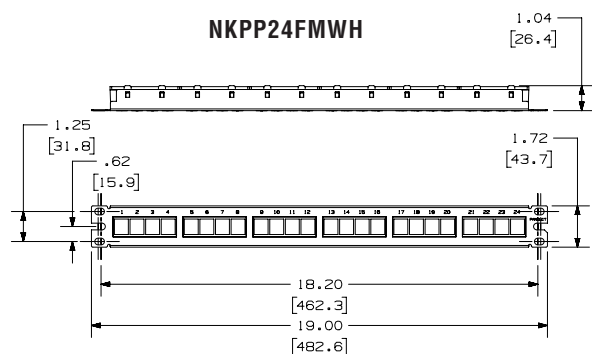

Dimensions are in inches. (Dimensions in brackets are metric).

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty



For more information
Visit us at www.panduit.com
Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

©2021 Panduit Corp.
ALL RIGHTS RESERVED.
NKSP70--WW-ENG
2/2021