
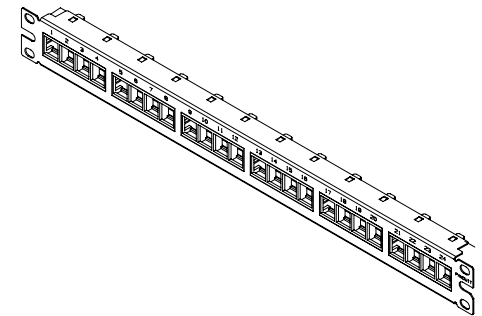


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT P/N	WEIGHT
NKPP24FMWH	7.51 LB/10 PCS (3408.5 g/10 PCS)

NOTES:

- SEE CURRENT CATALOG FOR VARIOUS APPLICATIONS WITH THIS WIRING SYSTEM.
- THE FLUSH MOUNT PATCH PANEL IS DESIGNED FOR MOUNTING TO 19" UNIVERSAL RACKS.
- PACKAGE CONTENTS:  
 (1) -24 PORT STAMPING  
 (6) -4 POSITION FACEPLATE (ASSEMBLED TO PANEL)  
 (1) -SCREW KIT (INCLUDES FOUR #12-24 SCREWS)
- DIMENSIONS IN [ ] ARE IN METRIC.

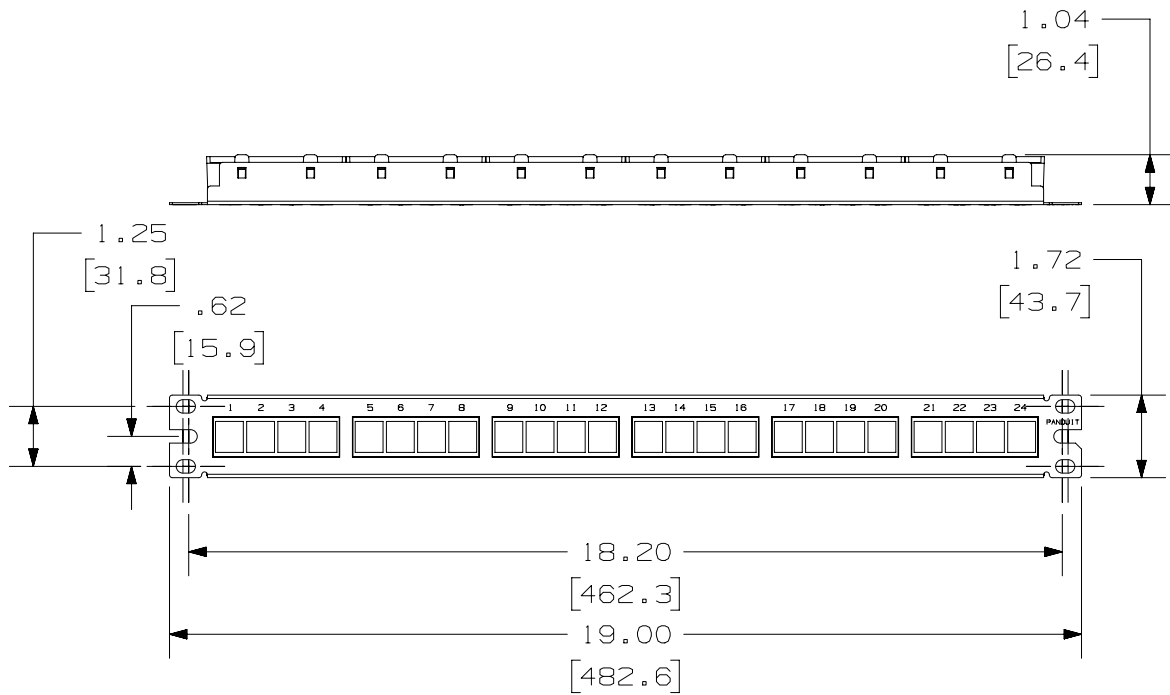

PART NUMBER		NKPP24FMWH		
TITLE		NETKEY 24 PORT FLUSH MOUNT PATCH PANEL		
		CUSTOMER DRAWING		
ITEM REVISION NAME		22906NBC/00		
DATASET FILE NAME		22906NBC_DC/00A		
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN (mm)		MATERIAL:		
.x ± .xxx ± .010 (.3)		PANEL: C.R.S. FACEPLATE: ABS		
.xx ± .03 (.8) ANGLES ±		DRAWING NUMBER:		
THIRD ANGLE PROJECTION		22906NBC-DC		
DRAWN BY	DATE	CHK	SCALE	SIZE
MDJR	2-12-21	JCO	NONE	A
REV	DATE	BY	CHK	APR
00A	2-12-21	MDJR	JCO	SKH
RELEASED TO PRODUCTION				
DESCRIPTION				
22906NBC-DC				
ECN				

D10100DA/14

2

1

2

1